

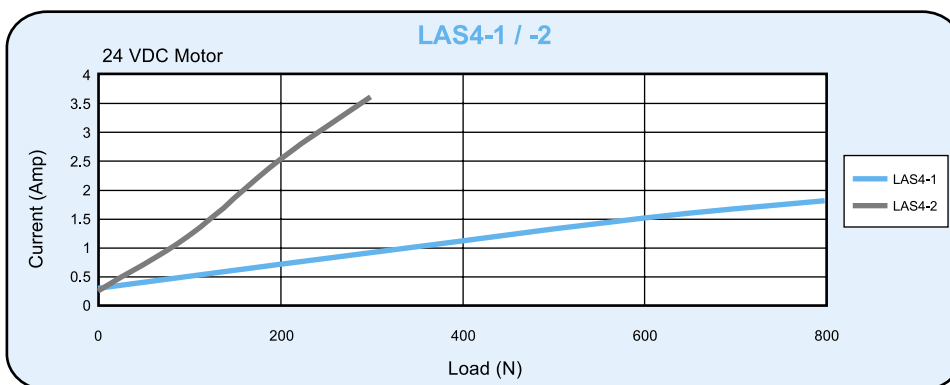


● LAS4 Specifications

Model	Thrust max. (N)	Pulling max. (N)	Holding max. (N)	force (mm/s) Load=Max./Load=0	Standard stroke (mm) : S					Duty cycle %	Max.current (A)	
					100	150	200	250	300		12VDC	24VDC
LAS4-1	800	800	800	10 / 15	100	150	200	250	300	10	5	1.8
LAS4-2	300	300	200	30 / 46	100	150	200	250	300	10	6	3.6

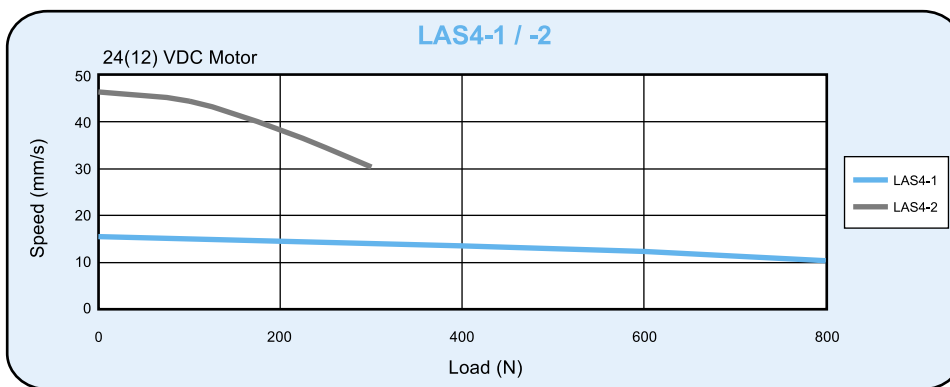

Note: The test results are obtained by using 24VDC power supply.

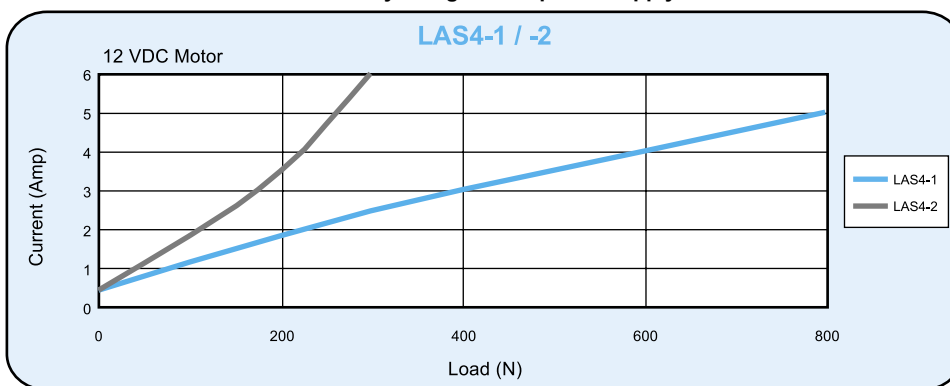

Note: The test results are obtained by using 12VDC power supply.

● Ordering Information

