

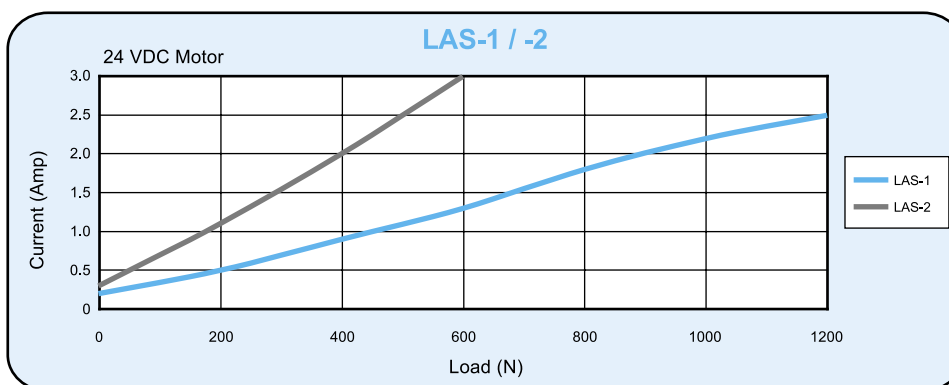


● LAS Specifications

Model	Thrust max. (N)	Pulling max. (N)	Holding max. (N)	force (mm/s) Load=Max./Load=0	Standard stroke (mm) : S					Duty cycle %	Max.current (A)	
					50	100	150	200	250		12VDC	24VDC
LAS-1	1200	1200	800	8 / 12	50	100	150	200	250	10	6	2.5
LAS-2	600	600	300	16 / 25	50	100	150	200	250	10	6	3

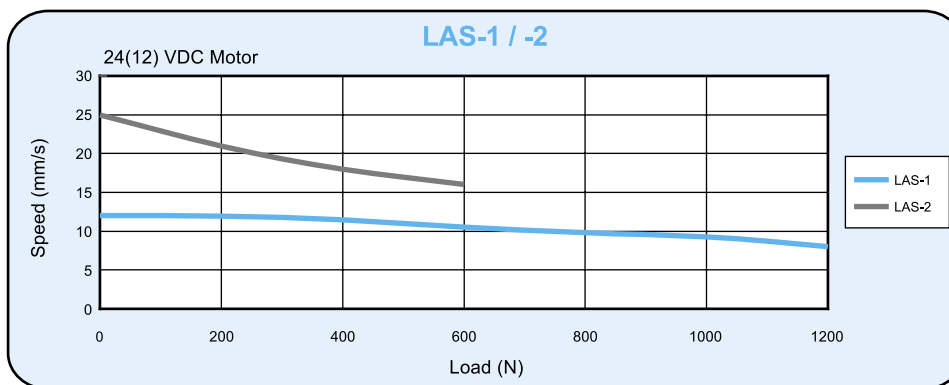

Note: The test results are obtained by using 24VDC power supply.

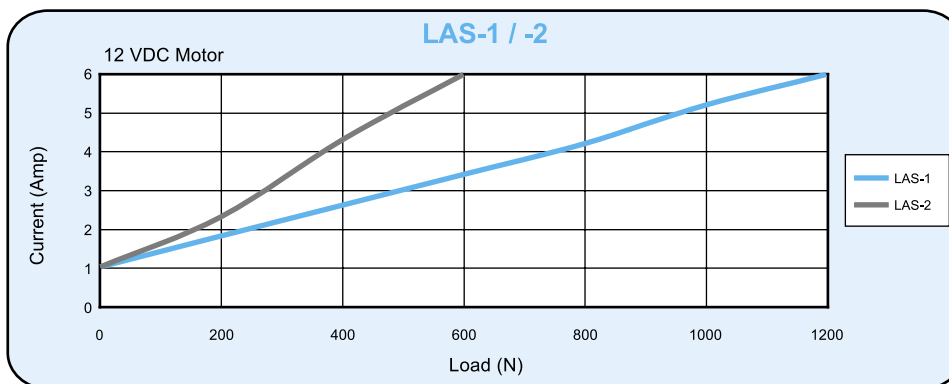

Note: The test results are obtained by using 12VDC power supply.

● Ordering Information

